



METRO

CONTENTS

| | |
|---------------------------------------|-----|
| Stainless Lab Worktables | 3-4 |
| Stainless Lab Worktable Accessories | 5 |
| MetroMax i® Lab Worktables | 6-7 |
| MetroMax i® Lab Worktable Accessories | 8 |
| HD Worktables | 9 |
| HD Mobile Worktables | 10 |
| HD Worktables with Overhead | 10 |
| HD Super™ Accessories | 11 |



Stainless Lab Worktables

- Corrosion-proof performance — stainless steel construction throughout.
- Easily cleaned smooth surfaces. Mobile units can be easily moved to clean behind table area.
- Available top materials include Type 304 stainless and TRESPA Phenolic resin (black or gray).
- Choose from a wide range of accessories and caster options to customize table.



13450974 with casters (ordered separately)

Lab Tables with Stainless Island Top and Solid HD Shelf

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 35.375 | 35.188 | 65 | 13450943 | 13450974 |
| 30.000 | 35.750 | 35.375 | 35.188 | 80 | 13450971 | 13450975 |
| 30.000 | 47.750 | 35.375 | 35.188 | 103 | 13450972 | 13450960 |
| 30.000 | 59.750 | 35.375 | 35.188 | 140 | 13450973 | 13450961 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.

Lab Tables with Stainless Island Top and 3-Sided Frame

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 35.375 | 35.188 | 58 | 13450976 | 13450980 |
| 30.000 | 35.750 | 35.375 | 35.188 | 70 | 13450977 | 13450981 |
| 30.000 | 47.750 | 35.375 | 35.188 | 91 | 13450978 | 11927100 |
| 30.000 | 59.750 | 35.375 | 35.188 | 119 | 13450979 | 13450983 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



13450983 with optional accessories and casters

Lab Tables with Stainless Backsplash Top and Solid HD Shelf

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 35.375 | 35.188 | 65 | 13450984 | 13450988 |
| 30.000 | 35.750 | 35.375 | 35.188 | 80 | 13450985 | 13450989 |
| 30.000 | 47.750 | 35.375 | 35.188 | 103 | 13450986 | 13450990 |
| 30.000 | 59.750 | 35.375 | 35.188 | 140 | 13450987 | 13450991 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



13450992 with optional accessory wire shelf

Lab Tables with Stainless Backsplash and 3-Sided Frame

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 35.375 | 35.188 | 58 | 13450992 | 13450996 |
| 30.000 | 35.750 | 35.375 | 35.188 | 70 | 13450993 | 13450997 |
| 30.000 | 47.750 | 35.375 | 35.188 | 91 | 13450994 | 11927101 |
| 30.000 | 59.750 | 35.375 | 35.188 | 119 | 13450995 | 13450999 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.

Stainless Lab Worktables

Lab Tables with Black Phenolic Top and Solid HD Shelf (Backsplash accessory ordered separately)



13451004

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 36.000 | 35.875 | 77 | 13451000 | 13451004 |
| 30.000 | 35.750 | 36.000 | 35.875 | 92 | 13451001 | 13451005 |
| 30.000 | 47.750 | 36.000 | 35.875 | 113 | 13451002 | 13451006 |
| 30.000 | 59.750 | 36.000 | 35.875 | 141 | 13451003 | 13451007 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.

Stainless Tables with Black Phenolic Top and 3-Sided Frame (Backsplash accessory ordered separately)

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 36.000 | 35.875 | 70 | 13451008 | 13451012 |
| 30.000 | 35.750 | 36.000 | 35.875 | 82 | 13451009 | 13451013 |
| 30.000 | 47.750 | 36.000 | 35.875 | 101 | 13451010 | 13451014 |
| 30.000 | 59.750 | 36.000 | 35.875 | 120 | 13451011 | 13451015 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



13451015 with accessories, casters, backsplash, and Starsys™ cart

Stainless Tables with Gray Phenolic Top and Solid HD Shelf (Backsplash accessory ordered separately)

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 36.000 | 35.875 | 77 | 13451016 | 13451020 |
| 30.000 | 35.750 | 36.000 | 35.875 | 92 | 13451017 | 13451021 |
| 30.000 | 47.750 | 36.000 | 35.875 | 113 | 13451018 | 13451022 |
| 30.000 | 59.750 | 36.000 | 35.875 | 141 | 13451019 | 13451023 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



13451020

Stainless Tables with Gray Phenolic Top and 3-Sided Frame (Backsplash accessory ordered separately)

| Width (in.) | Length (in.) | Work Surface Height | | Approx. Pkd. Wt. (lbs.) | Cat. No. Stationary | Cat. No. Mobile |
|-------------|--------------|---------------------|--------------|-------------------------|---------------------|-----------------|
| | | Stationary (in.) | Mobile (in.) | | | |
| 30.000 | 29.750 | 36.000 | 35.875 | 70 | 13451024 | 13451028 |
| 30.000 | 35.750 | 36.000 | 35.875 | 82 | 13451025 | 13451029 |
| 30.000 | 47.750 | 36.000 | 35.875 | 101 | 13451026 | 13451030 |
| 30.000 | 59.750 | 36.000 | 35.875 | 120 | 13451027 | 13451031 |

Leveling feet on stationary units have 1.250 vertical adjustment.

***Casters ordered separately.** Refer to Caster Selection Guide for more information.

Stainless Lab Tables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



13451031 with accessories, casters, backsplash, and Starsys™ cart

For Stainless Steel Mobile Worktables, Select Appropriate Casters from Chart Below. (4 brake casters are recommended for maximum stability)

Caster Selection Guide

| Caster Series | Wheel Material | Rollability | Floor Protection | Noise | 19123303 | 19037477 | 19063096 | 13451033 | 13450968 |
|----------------------------|---------------------|-------------|------------------|----------|--------------------|----------------------|---------------|---------------------------------|----------|
| | | | | | Load Rating (lbs.) | Corrosion Resistance | Cart Washable | Antimicrobial Additive in Wheel | |
| 19123303/13450966 (brake) | High Modulus Rubber | Good | Good | Low | 250 | Low | No | No | |
| 19037477/19033407A (brake) | Polyurethane | Good | Good | Moderate | 300 | Low | No | No | |
| 13450950/19063096 (brake) | Polyurethane | Good | Good | Moderate | 300 | High | No | No | |
| 13451032/13451033 (brake) | Polyurethane | Good | Good | Moderate | 300 | High | No | Yes | |
| 13450968/13450970 (brake) | Polyurethane | Good | Good | Moderate | 300 | High | Yes | No | |



NOTE: The total weight of the equipment and its load should not exceed three times the load rating per caster. Additional stem casters, in various sizes and wheel materials, are available. Contact your Fisher rep for more information.

Stainless Lab Worktable Accessories



Backsplash

Backsplash

4" (102mm) high. Attaches to phenolic table top using pre-drilled holes. Match length and color with selected countertop.

| Length (in.) | Approx. Pkd. Wt. (lbs.) | Cat. No. Black | Cat. No. Gray |
|--------------------------------|-------------------------|----------------|---------------|
| 27 ³ / ₄ | 5.5 | 13451034 | 13451037 |
| 33 ³ / ₄ | 6.5 | 13451035 | 13450957 |
| 45 ³ / ₄ | 7.5 | 13451036 | 13450958 |
| 57 ³ / ₄ | 9.5 | 13450948 | 13451038 |



Wire Shelf

Wire Shelf

Stainless or Epoxy-coated shelves available.

| Length (in.) | Approx. Pkd. Wt. (lbs.) | Cat. No. Stainless | Cat. No. Epoxy Coated |
|--------------------------------|-------------------------|--------------------|-----------------------|
| 22 ³ / ₈ | 6 | 13451039 | 19109113 |
| 28 ³ / ₈ | 7.5 | 13451040 | 19109114 |
| 40 ³ / ₈ | 10 | 13451041 | 19109115 |
| 52 ³ / ₈ | 12 | 13451042 | 19109116 |

Note: Shelves are load rated for a maximum of 150 lbs.



Stainless Keyboard Tray

Fits 48" and 60" table lengths
Cat. No. **13451043**

Note: Stainless keyboard tray and stainless drawer will both fit 60" (1524mm) long table.



Stainless Drawer




Fits 30", 36", 48" and 60" table lengths
Cat. No. **13451044**

Note: Stainless keyboard tray and stainless drawer will both fit 60" long table.



Surface Mount Swing Arm for Flat Monitor

Cat. No. **13450949**

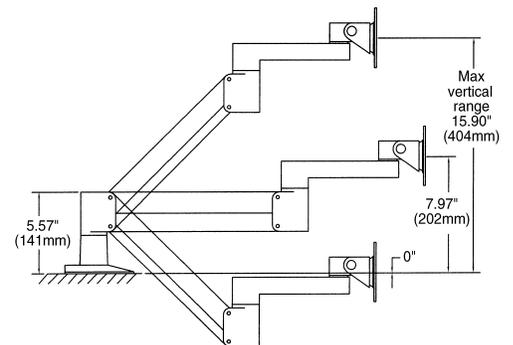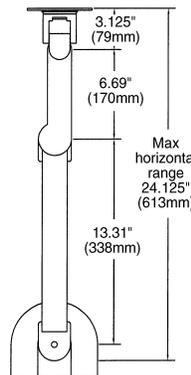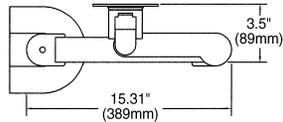

MetroMax i® Lab Worktables

- Advanced polymer construction provides excellent corrosion-resistance performance for the most corrosive lab environments.
- Table features smooth surfaces that are easy-to-clean. Mobile units can be easily moved to clean behind table area.
- Available top materials include Type 304 stainless and TRESPA phenolic resin (black or gray).
- Choose from a wide range of available accessories and caster options to customize table for a specific application.



11100246
(Shown with accessories,
casters and Starsys Cart)

Select Table Style from Chart Below and Following Page:

Worktables with Stainless Top and Backsplash with a Solid MetroMax i Shelf

| Width (in.) | Length (in.) | Work Surface Height (in.) | Overall Height (in.) | Approx. Pkd. Wt (lbs.) | Cat.No. Stationary | Cat. No. Mobile |
|-------------|--------------------------------|--------------------------------|--------------------------------|------------------------|--------------------|-----------------|
| 30 | 29 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 65 | 11100202 | 11100226 |
| 30 | 35 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 70 | 11100208 | 11100232 |
| 30 | 47 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 90 | 11100214 | 11100238 |
| 30 | 59 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 100 | 11100220 | 11100244 |

*Casters ordered separately. Refer to Caster Selection Guide below for more information. Lab Worktables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



11100226
(Featuring solid MetroMax i shelf shown with casters)

Worktables with Stainless Top and Backsplash with a 3-Sided Frame

| Width (in.) | Length (in.) | Work Surface Height (in.) | Overall Height (in.) | Approx. Pkd. Wt (lbs.) | Cat.No. Stationary | Cat. No. Mobile |
|-------------|--------------------------------|--------------------------------|--------------------------------|------------------------|--------------------|-----------------|
| 30 | 29 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 70 | 11100205 | 11100229 |
| 30 | 35 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 75 | 11100211 | 11100235 |
| 30 | 47 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 95 | 11100217 | 11100241 |
| 30 | 59 ³ / ₄ | 35 ¹ / ₂ | 39 ¹ / ₂ | 110 | 11100223 | 11100247 |

*Casters ordered separately. Refer to Caster Selection Guide below for more information. Lab Worktables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.

Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



11100229
(Shown with accessory wire shelf and casters)

MetroMax i Lab Worktables

Select Table Style from Chart Below:

Worktables with Black Phenolic Top and Solid MetroMax i Shelf



11100242
(Shown with backplash, accessories and casters)

| Width (in.) | Length (in.) | Work Surface Height (in.) | Overall Height (in.) | Approx. Pkd. Wt (lbs.) | Cat.No. Stationary | Cat. No. Mobile |
|-------------|--------------------------------|--------------------------------|--------------------------------|------------------------|--------------------|-----------------|
| 30 | 29 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 85 | 11100200 | 11100224 |
| 30 | 35 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 91 | 11100206 | 11100230 |
| 30 | 47 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 118 | 11100212 | 11100236 |
| 30 | 59 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 138 | 11100218 | 11100242 |

*Casters ordered separately. Refer to Caster Selection Guide below for more information. Lab Worktables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.
Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



11100245
(Shown with accessories and casters)

Worktables with Black Phenolic Top and 3-Sided Frame

| Width (in.) | Length (in.) | Work Surface Height (in.) | Overall Height (in.) | Approx. Pkd. Wt (lbs.) | Cat.No. Stationary | Cat. No. Mobile |
|-------------|--------------------------------|--------------------------------|--------------------------------|------------------------|--------------------|-----------------|
| 30 | 29 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 90 | 11100203 | 11100227 |
| 30 | 35 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 97 | 11100209 | 11100233 |
| 30 | 47 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 125 | 11100215 | 11100239 |
| 30 | 59 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 145 | 11100221 | 11100245 |

*Casters ordered separately. Refer to Caster Selection Guide below for more information. Lab Worktables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.
Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



11100243
(Shown with backplash, accessories and casters)

Worktables with Gray Phenolic Top and Solid MetroMax i Shelf

| Width (in.) | Length (in.) | Work Surface Height (in.) | Overall Height (in.) | Approx. Pkd. Wt (lbs.) | Cat.No. Stationary | Cat. No. Mobile |
|-------------|--------------------------------|--------------------------------|--------------------------------|------------------------|--------------------|-----------------|
| 30 | 29 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 85 | 11100201 | 11100225 |
| 30 | 35 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 91 | 11100207 | 11100231 |
| 30 | 47 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 118 | 11100213 | 11100237 |
| 30 | 59 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 138 | 11100219 | 11100243 |

*Casters ordered separately. Refer to Caster Selection Guide below for more information. Lab Worktables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.
Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.



11100246
(Shown with accessories and casters)

Worktables with Gray Phenolic Top and 3-Sided Frame

| Width (in.) | Length (in.) | Work Surface Height (in.) | Overall Height (in.) | Approx. Pkd. Wt (lbs.) | Cat.No. Stationary | Cat. No. Mobile |
|-------------|--------------------------------|--------------------------------|--------------------------------|------------------------|--------------------|-----------------|
| 30 | 29 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 90 | 11100204 | 11100228 |
| 30 | 35 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 97 | 11100210 | 11100234 |
| 30 | 47 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 125 | 11100216 | 11100240 |
| 30 | 59 ³ / ₄ | 36 ¹ / ₂ | 40 ¹ / ₂ | 145 | 11100222 | 11100246 |

*Casters ordered separately. Refer to Caster Selection Guide below for more information. Lab Worktables are load rated at 50 lbs. per sq. foot up to a maximum of 600 lbs. assuming evenly distributed load and caster specification meets requirement.
Note: Mobile posts include an adaptor insert that will accept Metro 5" stem casters.

For MetroMax i Mobile Worktables, Select Appropriate Casters from Chart Below.
(Four brake casters are recommended for maximum table stability)

Caster Selection Guide

| *Caster Series | Wheel Material | Rollability | Floor Protection | Noise | Load Rating (lbs.) | Corrosion Resistance | Cart Washable | Antimicrobial Additive in Wheel |
|---------------------------|---------------------|-------------|------------------|----------|--------------------|----------------------|---------------|---------------------------------|
| 19109105/19109104 (brake) | High Modulus Rubber | Good | Good | Low | 250 | Low | No | No |
| 1798738A/1798738B (brake) | Polyurethane | Good | Good | Moderate | 300 | Low | No | No |
| 11926303/11926302 (brake) | Polyurethane | Good | Good | Moderate | 300 | High | No | No |
| 19109108/19109107 (brake) | Polyurethane | Good | Good | Moderate | 300 | High | No | Yes |
| 19109106/13452200 (brake) | Polyurethane | Good | Good | Moderate | 300 | High | Yes | No |

NOTE: The total weight of the equipment and its load should not exceed three times the load rating per caster. Additional stem casters, in various sizes and wheel materials, are available. Contact your Fisher rep for more information.




MetroMax i Lab Worktable Accessories

Backsplash

4" high. Attaches to phenolic table top using pre-drilled holes. Match length and color with selected countertop.

| Length (in.) | Approx. Pkd. Wt. (lbs.) | Cat. No. Black | Cat. No. Gray |
|--------------------------------|-------------------------|----------------|---------------|
| 27 ³ / ₄ | 5.5 | 13451034 | 13451037 |
| 33 ³ / ₄ | 6.5 | 13451035 | 13450957 |
| 45 ³ / ₄ | 7.5 | 13451036 | 13450958 |
| 57 ³ / ₄ | 9.5 | 13450948 | 13451038 |

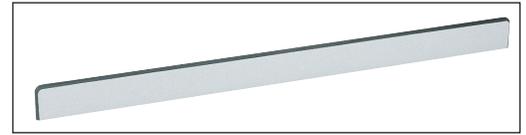

Keyboard Tray

Fits 48" and 60" table lengths.

Cat. No. **13452201** Note: Keyboard tray and drawer will both fit a 60" table.



Drawers

Fit 30", 36", 48" and 60" table lengths.

- 3" Cat. No. **19109117**
- 6" Cat. No. **19109119**
- 3" locking Cat. No. **19109118**
- 6" locking Cat. No. **19109120**

Note: Keyboard tray and drawer will both fit a 60" table.



Wire Shelf

Stainless or Epoxy-coated shelves available.




| Length (in.) | Approx. Pkd. Wt. (lbs.) | Cat. No. Stainless | Cat. No. Epoxy Coated |
|--------------------------------|-------------------------|--------------------|-----------------------|
| 22 ³ / ₈ | 6 | 13451039 | 19109113 |
| 28 ³ / ₈ | 7.5 | 13451040 | 19109114 |
| 40 ³ / ₈ | 10 | 13451041 | 19109115 |
| 52 ³ / ₈ | 12 | 13451042 | 19109116 |



Note: Shelves are load rated for a maximum of 150 lbs.

Surface Mount Swing Arm for Flat Monitor

Cat. No. **13450949**

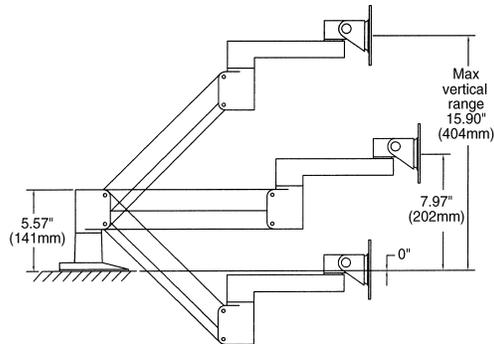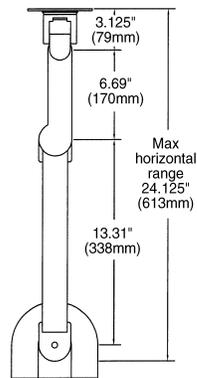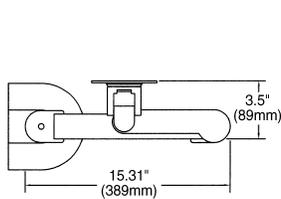

13450949

HD Worktables

Built for cleanliness and stability.

- Seamless 14-gauge Type 304 stainless steel work surface and support structure.
- Shipped knocked down and can be assembled in minutes without tools.

All Worktables are 34" high with stationary posts and leveling feet.



Worktable with Bottom Shelf

Standard Worktables — 30" Wide

| Length (in.) | Post Material | Bottom Shelf Material | Bottom 3-Sided Frame Material | Bottom H-Frame Material | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--------------|---------------|-----------------------|-------------------------------|-------------------------|-------------------------|----------|
| 48 | SS | SS | — | — | 90 | 11927122 |
| 60 | SS | SS | — | — | 130 | 11927125 |
| 72 | SS | SS | — | — | 170 | 11927128 |
| 96 | SS | SS | — | — | 226 | 11927131 |
| 60 | Chrome | Galvanized | — | — | 146 | 11927124 |
| 72 | Chrome | Galvanized | — | — | 180 | 11927127 |
| 96 | Chrome | Galvanized | — | — | 226 | 11927130 |
| 48 | SS | — | SS | — | 115 | 11927123 |
| 60 | SS | — | SS | — | 115 | 91152 |
| 72 | SS | — | SS | — | 142 | 91154 |
| 96 | SS | — | SS | — | 201 | 91156 |
| 60 | SS | — | — | SS | 115 | 11927126 |
| 72 | SS | — | — | SS | 142 | 11927129 |
| 96 | SS | — | — | SS | 202 | 11927132 |

SS = Stainless Steel

Standard Worktables — 36" Wide

| Length (in.) | Post Material | Bottom Shelf Material | Bottom 3-Sided Frame Material | Bottom H-Frame Material | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--------------|---------------|-----------------------|-------------------------------|-------------------------|-------------------------|----------|
| 60 | SS | SS | — | — | 125 | 11927134 |
| 72 | SS | SS | — | — | 130 | 11927137 |
| 96 | SS | SS | — | — | 185 | 11927140 |
| 60 | Chrome | Galvanized | — | — | 125 | 11927133 |
| 72 | Chrome | Galvanized | — | — | 130 | 11927136 |
| 96 | Chrome | Galvanized | — | — | 185 | 11927139 |
| 60 | SS | — | SS | — | 104 | 91153 |
| 72 | SS | — | SS | — | 106 | 91155 |
| 96 | SS | — | SS | — | 161 | 11927142 |
| 60 | SS | — | — | SS | 103 | 11927135 |
| 72 | SS | — | — | SS | 107 | 11927138 |
| 96 | SS | — | — | SS | 162 | 11927141 |

SS = Stainless Steel



Worktable with 3-Sided Frame

Standard Worktables — 44" Wide

| Length (in.) | Post Material | Bottom Shelf Material | Bottom 3-Sided Frame Material | Bottom H-Frame Material | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--------------|---------------|-----------------------|-------------------------------|-------------------------|-------------------------|----------|
| 60 | SS | SS | — | — | 136 | 11927144 |
| 72 | SS | SS | — | — | 160 | 11927148 |
| 96 | SS | SS | — | — | 202 | 11927152 |
| 60 | Chrome | Galvanized | — | — | 136 | 11927143 |
| 72 | Chrome | Galvanized | — | — | 160 | 11927147 |
| 96 | Chrome | Galvanized | — | — | 202 | 11927151 |
| 60 | SS | — | SS | — | 114 | 11927146 |
| 72 | SS | — | SS | — | 135 | 11927150 |
| 96 | SS | — | SS | — | 177 | 11927154 |
| 60 | SS | — | — | SS | 113 | 11927145 |
| 72 | SS | — | — | SS | 136 | 11927149 |
| 96 | SS | — | — | SS | 178 | 11927153 |

SS = Stainless Steel



Worktable with H-Frame

HD Mobile Worktables

All Mobile Worktables are 34" high. Mobile units have special posts and four 5" poly casters — 2 swivel/2 brake.

Mobile Worktables — 30" Wide

| Length (in.) | Post Material | Bottom Shelf Material | Bottom 3-Sided Frame Material | Bottom H-Frame Material | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--------------|---------------|-----------------------|-------------------------------|-------------------------|-------------------------|----------|
| 48 | SS | SS | — | — | 105 | 11927102 |
| 60 | SS | SS | — | — | 160 | 11927105 |
| 72 | SS | SS | — | — | 182 | 11926224 |
| 96 | SS | SS | — | — | 226 | 11927110 |
| 60 | Chrome | Galvanized | — | — | 146 | 11927104 |
| 72 | Chrome | Galvanized | — | — | 180 | 11927107 |
| 96 | Chrome | Galvanized | — | — | 226 | 11927109 |
| 48 | SS | — | SS | — | 130 | 11927103 |
| 60 | SS | — | SS | — | 139 | 1798735A |
| 72 | SS | — | SS | — | 155 | 91158 |
| 96 | SS | — | SS | — | 201 | 11927112 |
| 60 | SS | — | — | SS | 124 | 11927106 |
| 72 | SS | — | — | SS | 156 | 11927108 |
| 96 | SS | — | — | SS | 202 | 11927111 |

SS = Stainless Steel



Mobile Worktable

HD Worktables with Overhead

All Worktables with Overhead are 30" wide and have rear posts that are approximately 88" high. Cantilever shelves for overhead models are sold separately.


| Length (in.) | Post Material | Bottom Shelf Material | Bottom 3-Sided Frame Material | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--------------|---------------|-----------------------|-------------------------------|-------------------------|----------|
| 60 | SS | SS | — | 158 | 11927114 |
| 72 | SS | SS | — | 251 | 11927117 |
| 96 | SS | SS | — | 288 | 11927120 |
| 60 | Chrome | Galvanized | — | 214 | 11927113 |
| 72 | Chrome | Galvanized | — | 251 | 11927116 |
| 96 | Chrome | Galvanized | — | 288 | 11927119 |
| 60 | SS | — | SS | 196 | 11927115 |
| 72 | SS | — | SS | 230 | 11927118 |
| 96 | SS | — | SS | 267 | 11927121 |

All overhead models are fitted with stationary posts and leveling feet.
For overhead models in other sizes, contact your Fisher representative.
SS = Stainless Steel



Shown with optional Cantilever Shelf and Utility Rack

HD Super™ Accessories

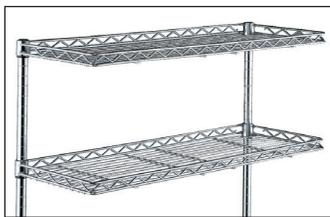

Cantilever Shelf —

| Width/Length (in.) | Fits Unit | Approx. Pkd. Wt. (lbs.) | Cat. No. Chrome | Cat. No. Stainless |
|--------------------|---------------------|-------------------------|-----------------|--------------------|
| 12x54 | 60" long | 11.8 | 19109109 | 19109110 |
| 12x60 | 72" long & 96" long | 12.7 | 19109111 | 17823791 |

Cantilever Shelf

HD Super™ Replacement Parts



3 1/2" Foot Plates
Cat. No. **11926310**



Post Clamps
Cat. No. **11926311**



Replacement HD Super™ Plastic Split Sleeves
4 pair per bag
Cat. No. **13452203**




Replacement HD Super™ Aluminum Split Sleeves with Zinc Ring
4 pair per bag
Cat. No. **11926313**



Replacement 5 1/2" Donut Bumpers
Cat. No. **11926314** Above fit 1 5/8" posts only.

Wall Mounting Brackets (not shown)
Cat. No. **11926312**

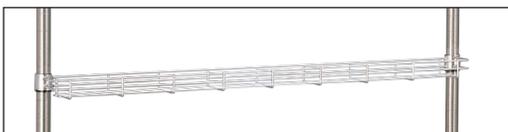

Utility Rack



Utility Hook



Deluxe Drawer

Accessories for Worktables with Overhead

Utility Racks for Overhead Models

Inside dimensions measure 1 15/16" high and 4 3/8" wide.

| Inside Length (in.) | Fits Units (in.) | Finish | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|---------------------|-------------------|---------------|-------------------------|----------|
| 51 9/16 | 60 long | Chrome-Plated | 7.7 | 19109100 |
| 57 9/16 | 72 long & 96 long | Chrome-Plated | 8.3 | 19109101 |

Utility Hook for Cantilever Shelves

| Width/Height/Depth (in.) | Finish | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--------------------------|-----------|-------------------------|----------|
| 3/8x37/16x1 11/16 | Chrome | 0.1 | 19109102 |
| 3/8x37/16x1 11/16 | Stainless | 0.1 | 19109103 |

Accessories for All Worktables

Economy Drawer

| Overall Dimensions Width/Length/Height (in.) | Dimensions Inside Bottom (in.) | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--|--------------------------------|-------------------------|----------|
| 14 1/4x28x5 3/4 | 10x16 | 6.8 | 19109112 |

Deluxe Drawer

Table accepts up to two drawers stacked.

| Overall Dimensions Width/Length/Height (in.) | Dimensions Inside Bottom (in.) | Approx. Pkd. Wt. (lbs.) | Cat. No. |
|--|--------------------------------|-------------------------|----------|
| 24x25 3/4x7 1/2 | 20x20 | 31 | 91159 |



© 2013 Thermo Fisher Scientific Inc. All rights reserved.
Trademarks used are owned as indicated at www.fishersci.com/trademarks.

In the United States:

For customer service, call 1-800-766-7000
To fax an order, use 1-800-926-1166
To order online: www.fishersci.com

In Canada:

For customer service, call 1-800-234-7437
To fax an order, use 1-800-463-2996
To order online: www.fishersci.ca



Part of Thermo Fisher Scientific